




EV100

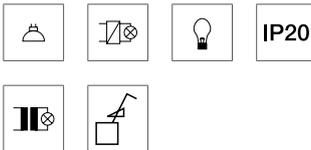

Remote control dimmer universal 1000W

Technical Features

Voltage

Rated operational voltage Ue	230 - 230 V
------------------------------	-------------

Frequency

Frequency	50 - 50 Hz
-----------	------------

Materials

Colour	Grey
RAL code	7035

Dimensions

Height	85 mm
Width	88.50 mm
Depth	65 mm

Power

Power consumption during operation	15 VA
Power consumption standby	3 W
Power incandescent lamp	20 - 1000 W

Use conditions

Operating temperature	-10 - 45 °C
-----------------------	-------------

Connection

Cross-section rigid conductor	1.5 - 10 mm ²
Cross-section flexible conductor	1 - 16 mm ²

Capacity

Number of modules	5
-------------------	---

Texts

Dimming principle	Automatic load detection
Installation mode	For mounting on DIN rail
Type of connection	With screw terminals
Junction	Connection for illuminated (max. 5 mA) or standard push-buttons

Sustainability

REACH-SVHC free	Yes
RoHS conform	Yes