




EV102

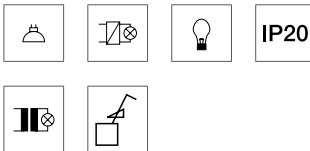

Universal remote control dimmer 1000W + display

Technical Features

Voltage

Rated operational voltage U_e 230 - 230 V

Frequency

Frequency 50 - 50 Hz

Materials

Colour Grey

RAL code 7035

Dimensions

Height 85 mm

Width 88.50 mm

Depth 65 mm

Power

Power consumption during operation 15 VA

Power consumption standby 3 W

Power incandescent lamp 20 - 1000 W

Use conditions

Operating temperature -10 - 45 °C

Connection

Cross-section rigid conductor 1.5 - 10 mm²

Cross-section flexible conductor 1 - 16 mm²

Capacity

Number of modules 5

Texts

Dimming principle Automatic load detection

Installation mode For mounting on DIN rail

Type of connection With screw terminals

Junction Connection for illuminated (max. 5 mA) or standard push-buttons

Equipment

Substation input Yes