




EV102

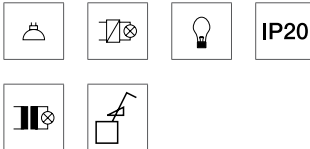

**Universal remote control dimmer 1000W + display**

**Technical Features**

**Voltage**

Rated operational voltage  $U_e$  230 - 230 V

**Frequency**

Frequency 50 - 50 Hz

**Materials**

Colour Grey

RAL code 7035

**Dimensions**

Height 85 mm

Width 88.50 mm

Depth 65 mm

**Power**

Power consumption during operation 15 VA

Power consumption standby 3 W

Power incandescent lamp 20 - 1000 W

**Use conditions**

Operating temperature -10 - 45 °C

**Connection**

Cross-section rigid conductor 1.5 - 10 mm<sup>2</sup>

Cross-section flexible conductor 1 - 16 mm<sup>2</sup>

**Capacity**

Number of modules 5

**Texts**

Dimming principle Automatic load detection

Installation mode For mounting on DIN rail

Type of connection With screw terminals

Junction Connection for illuminated (max. 5 mA) or standard push-buttons

**Equipment**

Substation input Yes