


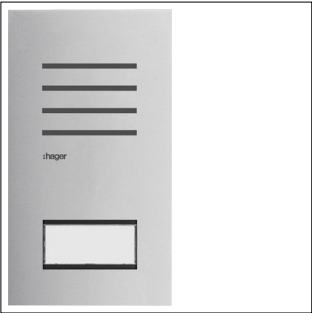

REQ001X



IK07

IP54



Door station AUDIO 1/1 2-wire stainless steel matt one

Technical Features

Materials

Surface finish	Matt
Material	Stainless steel

Controls and indicators

Number of call buttons	1
------------------------	---

Voltage

Operating voltage	24 - 24 V
-------------------	-----------

Dimensions

Dimensions	242 x 133.50 mm
Height	242 mm
Width	133.50 mm
Depth	25 mm

Use conditions

Operating temperature	-20 - 55 °C
Storage/transport temperature	-30 - 80 °C

Functions

Door communication type	Audio
-------------------------	-------

Connection

Conductor cross-section	0 - 0 mm ²
-------------------------	-----------------------

Installation, mounting

Mounting on	Flush mounting Surface mounting
-------------	------------------------------------

Texts

Installation mode	For vertical mounting Break-proof flush-mounted call buttons Installation in surface-mounted or flush-mounted housings
Junction	Pluggable connection terminal block with screw terminals
Lighting	Durable, homogeneous, white LED call push-button backlighting
Protection	Loudspeaker and microphone protected against sabotage