


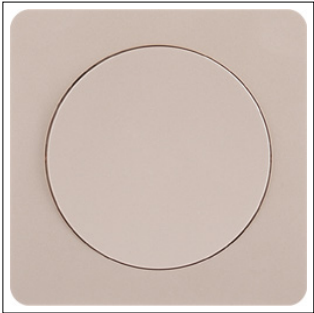

WGCXR111PEG

10A 1G press round switch;eg

Technical Features

Electric current	
Switching current	10 A
Voltage	
Rated voltage	250 V
Architecture	
Control/operation element	Single rocker
Materials	
Colour	Gold
Surface finish	Matt
Material	Polycarbonate (PC)
Treatment	Varnished
Transparent	No
Dimensions	
Height	86 mm
Width	86 mm
Depth	25 mm
Built-in depth flush-mounted boxes	35 mm
Controls and indicators	
Number of buttons	1
Connectivity	
Type of connection	Screw terminal
Safety	
Ingress Protection (IP) class	IP20
Texts	
Switch mode	1-way
Sustainability	
RoHS conform	Yes