




RED011X

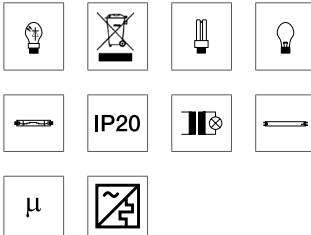

Bus line power supply with relay RMD light grey/grey

Technical Features

Capacity

Number of modules	6
-------------------	---

Dimensions

Height	90 mm
Width	106 mm
Depth	67 mm

Materials

Colour	Light grey
--------	------------

Connection

Number of connectable participants	32
------------------------------------	----

Use conditions

Operating temperature	-5 - 45 °C
-----------------------	------------

Installation, mounting

Mounting on	DIN rail
-------------	----------

Power

230 V incandescent and halogen lamp	2300 W
Fluorescent lamps in duo circuit	1000 W

Voltage

Input voltage	230 - 230 V
Output voltage	22 - 26 V
Operating voltage	230 - 230 V
Operating voltage at AC 60 Hz	230 - 230 V

Electric current

Output current	1250 mA
----------------	---------

Frequency

Frequency	50 - 60 Hz
-----------	------------

Safety

Ingress Protection (IP) class	IP20
-------------------------------	------

Texts

Junction	With connection for floating output Infeed output for bus components Potential-free door release and light switching contact
----------	--

Sustainability

REACH-SVHC free	Yes
RoHS conform	Yes