




41102007

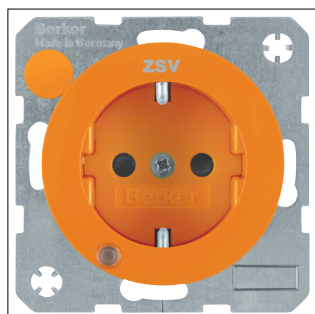

**SCHUKO soc.out. LED+"ZSV" impr.,enhncd contact prot.,screw-in lift ,R.1.3,or.**

#### Technical Features

##### Voltage

|               |       |
|---------------|-------|
| Rated voltage | 250 V |
|---------------|-------|

##### Electric current

|               |      |
|---------------|------|
| Rated current | 16 A |
|---------------|------|

##### Frequency

|           |            |
|-----------|------------|
| Frequency | 50 - 60 Hz |
|-----------|------------|

##### Materials

|                |               |
|----------------|---------------|
| Colour         | Orange        |
| RAL code       | 2003          |
| Surface finish | Glossy        |
| Material       | Thermoplastic |
| Treatment      | Untreated     |

##### Dimensions

|                 |       |
|-----------------|-------|
| Height          | 71 mm |
| Width           | 71 mm |
| Number of units | 1     |
| Built-in depth  | 32 mm |

##### Installation, mounting

|             |                |
|-------------|----------------|
| Mounting on | Flush mounting |
|-------------|----------------|

##### Connectivity

|                    |                                 |
|--------------------|---------------------------------|
| Type of connection | Screw terminal                  |
| Mounting type      | Screw mounting<br>Claw mounting |

##### Equipment

|                                   |        |
|-----------------------------------|--------|
| Connector/plug type socket outlet | SCHUKO |
| Rotated central insert            | No     |
| With hinged lid                   | No     |
| With round protective earth pin   | No     |
| With signal lamp                  | No     |
| With lock                         | No     |

##### Accessories

|                     |     |
|---------------------|-----|
| Has labelling field | Yes |
|---------------------|-----|

##### Capacity

|                   |   |
|-------------------|---|
| Number of modules | 1 |
|-------------------|---|

##### Controls and indicators

|                                               |                                    |
|-----------------------------------------------|------------------------------------|
| Type of lighting for the installation devices | Integrated operating control light |
|-----------------------------------------------|------------------------------------|

##### Safety

|                                  |      |
|----------------------------------|------|
| With enhanced contact protection | Yes  |
| Impact resistance IK             | IK05 |
| Ingress Protection (IP) class    | IP20 |

##### Functions

|                           |     |
|---------------------------|-----|
| With orientation lighting | No  |
| With function lighting    | Yes |

##### Texts

|         |                     |
|---------|---------------------|
| Imprint | With imprint "ZSV"  |
| Cover   | Central cover plate |

|                    |                              |
|--------------------|------------------------------|
| <b>Texts</b>       |                              |
| Protection         | Enhanced contact protection  |
| Type of connection | With screw-in lift terminals |

|                     |  |
|---------------------|--|
| <b>Suitable for</b> |  |
| R.x                 |  |