


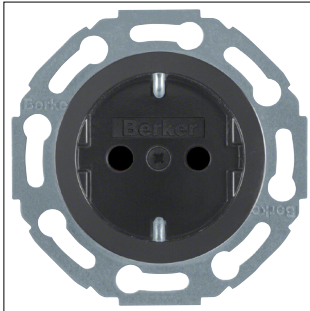

475501

SCHUKO soc.out.,enhncd contact prot.,mounting orient. var. in 45°step,1930/glass

Technical Features

Electric current

Rated current	16 A
---------------	------

Voltage

Rated voltage	250 V
Nominal voltage	250 - 250 V

Frequency

Frequency	50 - 60 Hz
-----------	------------

Materials

Colour	Black
RAL code	9005
Surface finish	Glossy
Material	Duroplastic
Treatment	Untreated

Dimensions

Height	71 mm
Width	71 mm
Depth	42 mm
Number of units	1
Built-in depth flush-mounted boxes	31 mm
Built-in depth	32 mm

Connection

Connector/plug type	Plugable clamp
Conductor cross-section	1.0 - 2.5 mm ²

Installation, mounting

Mounting on	Flush mounting
-------------	----------------

Connectivity

Type of connection	Plug-in connection
Mounting type	Screw mounting Claw mounting

Equipment

Connector/plug type socket outlet	SCHUKO
Rotated central insert	Yes
With hinged lid	No
With round protective earth pin	No
With signal lamp	No
With lock	No

Accessories

Has labelling field	No
---------------------	----

Capacity

Number of modules	1
-------------------	---

Safety

With enhanced contact protection	Yes
Impact resistance IK	IK02
Ingress Protection (IP) class	IP20

Functions

With orientation lighting	No
With function lighting	No

Product Datasheet

475501

Texts	
Imprint	Without imprint
Cover	Central cover plate
Protection	Enhanced contact protection
Type of connection	With plug-in terminals

Suitable for	
Serie 1930 / Serie Glas	

Sustainability	
Halogen free	Yes
RoHS conform	Yes