


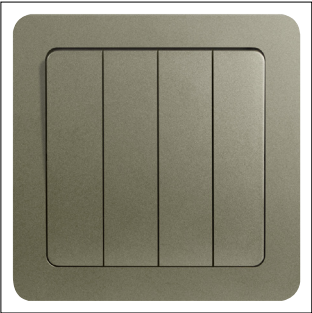

WGCXL142NB

16AX 4G 2W switch;nb

Technical Features

|                                    |                    |
|------------------------------------|--------------------|
| <b>Electric current</b>            |                    |
| Switching current                  | 16 A               |
| <b>Voltage</b>                     |                    |
| Rated voltage                      | 250 V              |
| <b>Materials</b>                   |                    |
| Colour                             | Bronze             |
| Surface finish                     | Matt               |
| Material                           | Polycarbonate (PC) |
| Treatment                          | Varnished          |
| <b>Controls and indicators</b>     |                    |
| Number of buttons                  | 4                  |
| <b>Dimensions</b>                  |                    |
| Dimensions                         | 86 x 86 mm         |
| Built-in depth flush-mounted boxes | 35 mm              |
| <b>Safety</b>                      |                    |
| Ingress Protection (IP) class      | IP20               |
| <b>Architecture</b>                |                    |
| Control/operation element          | 4-gang rocker      |
| <b>Electric current</b>            |                    |
| Rated current                      | 16 A               |
| <b>Texts</b>                       |                    |
| Switch mode                        | 2-way              |
| <b>Sustainability</b>              |                    |
| RoHS conform                       | Yes                |