


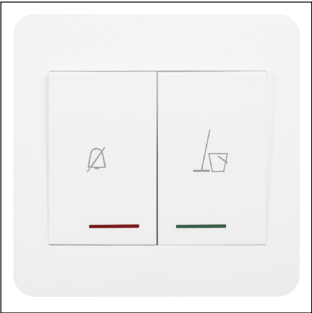

WGMHDC

16AX DND&MUR SWITCH W/ LED (INDOOR)

Technical Features

Electric current	
Switching current	16 A
Voltage	
Rated voltage	250 V
Frequency	
Frequency	50 - 60 Hz
Materials	
Colour	White
Surface finish	Glossy
Material	Polycarbonate (PC)
Treatment	Untreated
Controls and indicators	
Number of buttons	2
Dimensions	
Dimensions	86 x 86 mm
Safety	
Ingress Protection (IP) class	IP20
Architecture	
Control/operation element	Double rocker
Electric current	
Rated current	16 A
Sustainability	
REACH-SVHC free	Yes
RoHS conform	Yes