


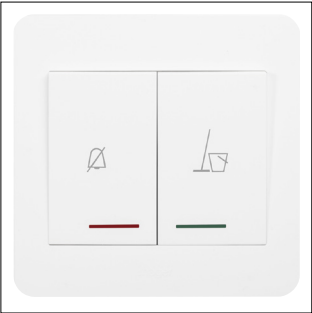

WGMHDC

16AX DND&MUR SWITCH W/ LED (INDOOR)

Technical Features

Electric current

|                   |      |
|-------------------|------|
| Switching current | 16 A |
|-------------------|------|

Voltage

|               |       |
|---------------|-------|
| Rated voltage | 250 V |
|---------------|-------|

Frequency

|           |            |
|-----------|------------|
| Frequency | 50 - 60 Hz |
|-----------|------------|

Materials

|                |                    |
|----------------|--------------------|
| Colour         | White              |
| Surface finish | Glossy             |
| Material       | Polycarbonate (PC) |
| Treatment      | Untreated          |

Controls and indicators

|                   |   |
|-------------------|---|
| Number of buttons | 2 |
|-------------------|---|

Dimensions

|            |            |
|------------|------------|
| Dimensions | 86 x 86 mm |
|------------|------------|

Safety

|                               |      |
|-------------------------------|------|
| Ingress Protection (IP) class | IP20 |
|-------------------------------|------|

Architecture

|                           |               |
|---------------------------|---------------|
| Control/operation element | Double rocker |
|---------------------------|---------------|

Electric current

|               |      |
|---------------|------|
| Rated current | 16 A |
|---------------|------|

Sustainability

|                 |     |
|-----------------|-----|
| REACH-SVHC free | Yes |
| RoHS conform    | Yes |