


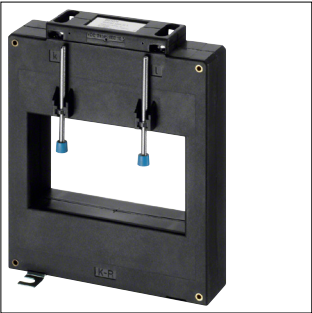

SRH30005

Bar/Cable-through Current Transformer BG 1274 3000/5A 15VA Class 1

Technical Features

Functions

Accuracy class	1
----------------	---

Power

Power	15 VA
Total power loss under I _N	23 W

Dimensions

Height	198 mm
Width	160 mm
Depth	40 mm
Height of opening	72 mm
Width of opening	122 mm

Connectivity

Type of connection	Screw terminal
--------------------	----------------

Frequency

Frequency	50 - 60 Hz
-----------	------------

Voltage

Rated insulation voltage U _i	3000 V
---	--------

Use conditions

Operating temperature	-40 - 40 °C
Storage/transport temperature	-40 - 40 °C

Connection

Cross-section flexible conductor	1.5 - 6 mm ²
Cross-section rigid conductor	1.5 - 6 mm ²

Safety

Ingress Protection (IP) class	IP10
-------------------------------	------

Electric current

Max. intensity of primary	3000 A
Max. intensity of secondary	5 A

Installation, mounting

Mounting on	DIN rail Mounting plate
-------------	----------------------------

Sustainability

Halogen free	Yes
REACH-SVHC free	Yes
RoHS conform	Yes