


Product Datasheet

WGDHSL

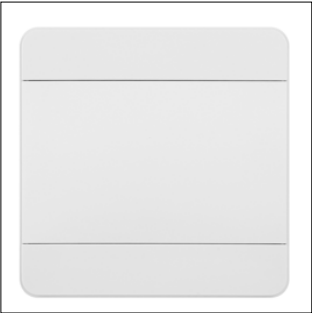

WGDHSL

sleeping light

Technical Features

Voltage

Rated voltage	230 V
---------------	-------

Frequency

Frequency	50-60 Hz
-----------	----------

Lighting

Type of lamp	LED
--------------	-----

Materials

Colour	White
RAL code	9010
Surface finish	Glossy
Material	Polycarbonate (PC)
Treatment	Untreated

Dimensions

Height	34 mm
Width	86 mm
Depth	34 mm

Connection

Conductor cross-section	0-1.5 mm ²
-------------------------	-----------------------

Connectivity

Mounting type	Screw mounting
---------------	----------------

Safety

Ingress Protection (IP) class	IP20
-------------------------------	------

Use conditions

Operating temperature	-5-45 °C
-----------------------	----------

Suitable for

shark	
-------	--

Sustainability

REACH-SVHC free	Yes
RoHS conform	Yes