


Product Datasheet

WPSS82

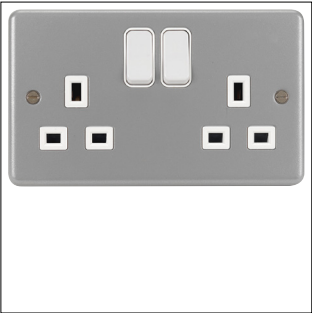

WPSS82

2 Gang Double Pole Switched Socket

Technical Features

Electric current	
Rated current	13 A

Voltage	
Rated voltage	250 V
Nominal voltage	250 - 250 V

Materials	
Colour	Grey
Surface finish	Glossy
Material	Steel
Treatment	Epoxy

Dimensions	
Height	86 mm
Width	146 mm
Depth	53.20 mm

Installation, mounting	
Mounting on	Flush mounting
Mounting-/Connection Position	Horizontal

Connectivity	
Type of connection	Screw terminal
Mounting type	Screw mounting

Equipment	
Connector/plug type socket outlet	British Standard
Rotated central insert	No
With hinged lid	No
With round protective earth pin	No
With signal lamp	No

Accessories	
Has labelling field	No

Capacity	
Number of modules	0

Safety	
Ingress Protection (IP) class	IP20

Functions	
With orientation lighting	No
With function lighting	No

Texts	
Imprint	Without imprint
Cover	Full cover plate
Wiring	With double earth connection
Protection	Enhanced contact protection

Sustainability	
REACH-SVHC free	Yes
RoHS conform	Yes