


Product Datasheet

WGMCH2

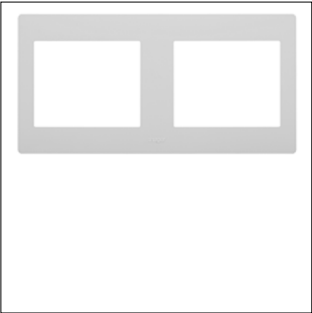

WGMCH2

2G multi-gang frame (horizontal)

Technical Features

Capacity

Number of gangs	2
Number of modules	0

Materials

Colour	White
Surface finish	Glossy
Material	Polycarbonate (PC)
Contains recycled material (% of total plastic weight)	0 %
Treatment	Untreated

Dimensions

Height	8 mm
Width	86 mm
Depth	8 mm
Number of units horizontal	2
Number of units vertical	2

Accessories

Has labelling field	No
---------------------	----

Installation, mounting

Mounting on	Mounting plate
-------------	----------------

Safety

Ingress Protection (IP) class	IP20
Impact resistance IK	IK02

Use conditions

Operating temperature	-20-45 °C
-----------------------	-----------

Sustainability

RoHS conform	Yes
--------------	-----