


303520

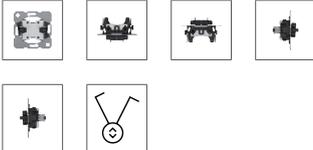

Blind switch 1pole, blind control

Technical Features

Controls and indicators

Venetian blind switch type 1-pole switch

Materials

Surface finish Matt
 Material Metal
Plastic
 Treatment Untreated

Voltage

Rated voltage 250 V

Electric current

Switching current 10 AX (100W LED (SBL))
 Switching current 10 A

Safety

Ingress Protection (IP) class IP20

Texts

Switch mode With mechanical and electrical interlock to prevent mutual switch-on
 Type of connection With plug-in terminals
 Installation mode With spreader claws

Suitable for

B.3 / B.7 / K.1 / K.5 / Q.1 / Q.3 / R.1 / R.3 / R.8 / S.1