


Product Datasheet

BTC480E

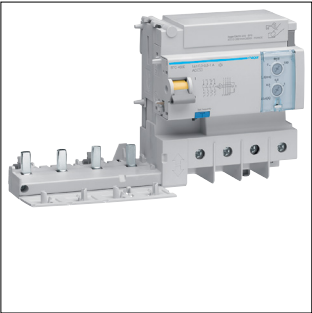

BTC480E

Earth leakage add-on-block 4P 125A Adjustable type AC

Technical Features

Electric current

Rated current	125 A
Rated residual operating current I _{dn}	300 mA
	500 mA
	1000 mA

Architecture

Number of poles	4
-----------------	---

Safety

Residual current type	AC
-----------------------	----

Voltage

Rated insulation voltage U _i	500 V
Rated impulse withstand voltage U _{imp}	6000 V

Connection

Cross-section of input and output with screws, for massive conductors	10 - 70 mm ²
Cross-section of input and output with screws, for flexible conductors	10 - 50 mm ²

Connectivity

Type of connection	Screw terminal
Down connection alignment for modular devices	Aligned terminal

Dimensions

Height	103 mm
Width	213 mm
Depth	69 mm

Sustainability

RoHS conform	Yes
--------------	-----

Illustrations | Drawings

