


# Product Datasheet

## HWX040H

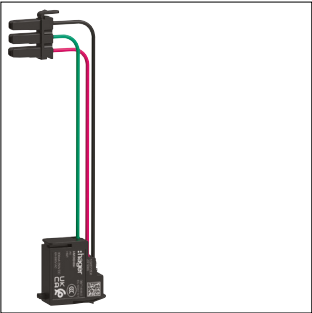

HWX040H

### Auxiliary Switch HW1 (AX)

#### Technical Features

<b>Electric current</b>	
Rated current 230 V AC15	4 A
<b>Connectivity</b>	
Mounting type	Click mounting
<b>Connection</b>	
Type of contacts	1x changeover
<b>Voltage</b>	
Rated insulation voltage $U_i$	690 V
Rated impulse withstand voltage $U_{imp}$	1500 V
Type voltage supply	AC/DC
<b>Frequency</b>	
Frequency	50 - 60 Hz
<b>Endurance</b>	
Number of mechanical operations	15000
<b>Use conditions</b>	
Operating temperature	-25 - 70 °C
<b>Endurance</b>	
Electric endurance in number of cycles	3025
<b>Use conditions</b>	
Storage/transport temperature	-40 - 70 °C
<b>Power</b>	
Total power loss under IN	0 W
<b>Safety</b>	
Ingress Protection (IP) class	IP4X
<b>Sustainability</b>	
REACH-SVHC free	Yes
RoHS conform	Yes