


Product Datasheet

WXF641

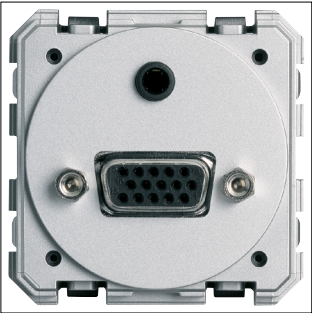

WXF641

SUB-D15 (VGA+minijack) gallery screw ter

Technical Features

Connection

Connector/plug type	VGA
Number of connections	2

Materials

Colour	Grey
RAL code	7011
Surface finish	Matt
Material	Polycarbonate (PC)
Treatment	Untreated

Dimensions

Height	45 mm
Width	45 mm
Depth	34.70 mm
Built-in depth flush-mounted boxes	35 mm

Connectivity

Mounting type	Claw mounting Screw connection
---------------	-----------------------------------

Equipment

Shielded	No
With dust cover	No

Safety

Ingress Protection (IP) class	IP20
Impact resistance IK	IK02

Use conditions

Operating temperature	-10 - 35 °C
-----------------------	-------------

Texts

Outlet	With straight outlet
Labelling	Without labelling
Shielding	Housing unshielded
Supporting plate/supporting ring	Without supporting ring

Suitable for

gallery	
---------	--

Sustainability

Halogen free	Yes
REACH-SVHC free	Yes
RoHS conform	Yes