


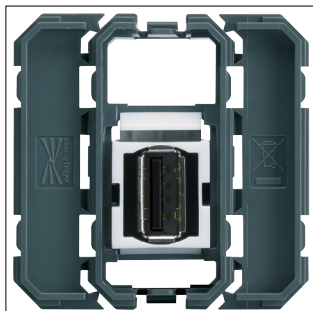

WXF642

## USB 2.0 gallery screw terminal

### Technical Features

#### Connection

|                       |     |
|-----------------------|-----|
| Connector/plug type   | USB |
| Number of connections | 0   |

#### Frequency

|           |            |
|-----------|------------|
| Frequency | 50 - 60 Hz |
|-----------|------------|

#### Materials

|                |                    |
|----------------|--------------------|
| Colour         | Grey               |
| RAL code       | 7011               |
| Surface finish | Matt               |
| Material       | Polycarbonate (PC) |
| Treatment      | Untreated          |

#### Dimensions

|                                    |       |
|------------------------------------|-------|
| Height                             | 40 mm |
| Width                              | 45 mm |
| Built-in depth flush-mounted boxes | 35 mm |

#### Connectivity

|               |                                   |
|---------------|-----------------------------------|
| Mounting type | Claw mounting<br>Screw connection |
|---------------|-----------------------------------|

#### Equipment

|                 |    |
|-----------------|----|
| Shielded        | No |
| With dust cover | No |

#### Safety

|                               |      |
|-------------------------------|------|
| Ingress Protection (IP) class | IP20 |
| Impact resistance IK          | IK02 |

#### Use conditions

|                       |             |
|-----------------------|-------------|
| Operating temperature | -10 - 35 °C |
|-----------------------|-------------|

#### Texts

|                                  |                         |
|----------------------------------|-------------------------|
| Outlet                           | With straight outlet    |
| Labelling                        | Without labelling field |
| Shielding                        | Housing unshielded      |
| Supporting plate/supporting ring | Without supporting ring |

#### Suitable for

|         |  |
|---------|--|
| gallery |  |
|---------|--|

#### Sustainability

|                 |     |
|-----------------|-----|
| REACH-SVHC free | Yes |
| RoHS conform    | Yes |