


# Product Datasheet

## WXF644

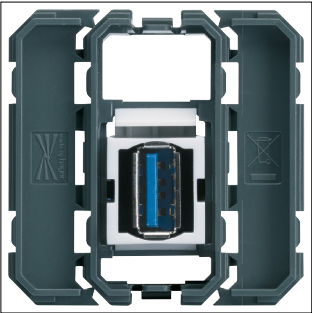

WXF644

### USB 3.0 socket gallery passthrough

#### Technical Features

##### Connection

Connector/plug type	USB
Number of connections	0

##### Frequency

Frequency	50 - 60 Hz
-----------	------------

##### Materials

Colour	Grey
RAL code	7011
Surface finish	Matt
Material	Polycarbonate (PC)
Treatment	Untreated

##### Dimensions

Height	40 mm
Width	45 mm
Built-in depth flush-mounted boxes	35 mm

##### Connectivity

Mounting type	Claw mounting Screw connection
---------------	-----------------------------------

##### Equipment

Shielded	No
With dust cover	No

##### Safety

Ingress Protection (IP) class	IP20
Impact resistance IK	IK02

##### Use conditions

Operating temperature	-10 - 35 °C
-----------------------	-------------

##### Texts

Outlet	With straight outlet
Labelling	Without labelling field
Shielding	Housing unshielded
Supporting plate/supporting ring	Without supporting ring

##### Suitable for

gallery	
---------	--

##### Sustainability

Halogen free	Yes
REACH-SVHC free	Yes
RoHS conform	Yes