


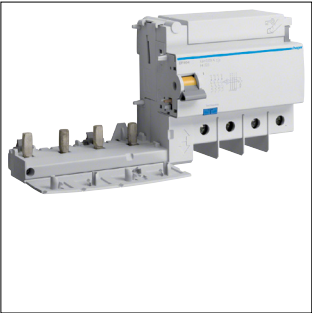

BF464

Earth leakage add-on block 4P 63A 300mA AC Class

Technical Features

Architecture

Neutral position	Left
Number of poles	4

Capacity

Number of modules	3
-------------------	---

Voltage

Rated operational voltage U_e	230 - 400 V
Rated insulation voltage U_i	500 V
Rated impulse withstand voltage U_{imp}	4000 V

Frequency

Frequency	50 - 50 Hz
-----------	------------

Electric current

Rated residual operating current I_{dn}	300 mA
Rated current	63 A

Connectivity

Type of connection	Screw terminal
Down connection alignment for modular devices	Aligned terminal

Installation, mounting

Nominal tightening torque	2.80 - 2.80 Nm
Nominal tightening torque down terminal	2.90 - 2.90 Nm

Dimensions

Height	70 mm
Width	35 mm
Depth	92 mm