


Product Datasheet

HWX041H

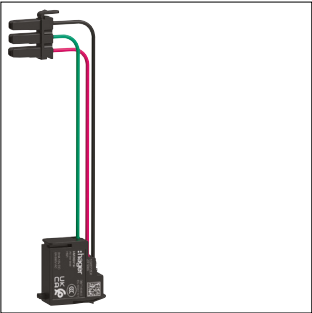

HWX041H

Auxiliary Switch low-level HW1 (AX)

Technical Features

Electric current	
Rated current 230 V AC15	2 A
Connectivity	
Mounting type	Click mounting
Connection	
Type of contacts	1x changeover
Voltage	
Rated insulation voltage Ui	690 V
Rated impulse withstand voltage Uimp	1500 V
Type voltage supply	AC/DC
Frequency	
Frequency	50 - 60 Hz
Endurance	
Number of mechanical operations	15000
Use conditions	
Operating temperature	-25 - 70 °C
Endurance	
Electric endurance in number of cycles	3025
Use conditions	
Storage/transport temperature	-40 - 70 °C
Power	
Total power loss under IN	0 W
Safety	
Ingress Protection (IP) class	IP4X
Sustainability	
REACH-SVHC free	Yes
RoHS conform	Yes