


# Product Datasheet

## K070

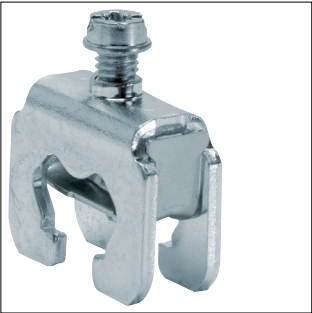

K070

Busbar terminal 1,5mm²-16mm², for 12x5mm busbars, for copper conductors

Technical Features

Connection

Cross-section flexible conductor	1.5 - 16 mm²
Cross-section rigid conductor	16 mm²

Installation, mounting

Nominal tightening torque	1 - 1 Nm
---------------------------	----------

Dimensions

Height busbar	5 mm
Width/thickness busbar	12 - 12 mm

Electric current

Rated current	65 A
---------------	------

Sustainability

REACH-SVHC free	Yes
RoHS conform	Yes