


Product Datasheet

WXF432

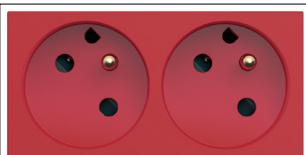

WXF432

Double socket with detrompage for trunking gallery 2P+E 16A

Technical Features

Electric current

Rated current	16 A
---------------	------

Voltage

Nominal voltage	250 - 250 V
-----------------	-------------

Use conditions

Operating temperature	-10 - 35 °C
-----------------------	-------------

Frequency

Frequency	50 - 60 Hz
-----------	------------

Materials

Colour	Red
RAL code	3020
Surface finish	Matt
Material	Polycarbonate (PC)
Treatment	Untreated

Dimensions

Height	42.50 mm
Width	90 mm
Depth	45 mm
Number of units	2
Built-in depth flush-mounted boxes	50 mm

Installation, mounting

Mounting on	Wall duct
-------------	-----------

Connectivity

Mounting type	Click mounting
---------------	----------------

Equipment

Connector/plug type socket outlet	French norm NF
Rotated central insert	Yes
With hinged lid	No
With round protective earth pin	Yes
With signal lamp	No

Accessories

Has labelling field	No
---------------------	----

Capacity

Number of modules	4
-------------------	---

Safety

With enhanced contact protection	Yes
Impact resistance IK	IK07
Ingress Protection (IP) class	IP20

Functions

With orientation lighting	No
With function lighting	No

Texts

Imprint	Without imprint
Cover	Complete housing
Protection	Enhanced contact protection

Product Datasheet

WXF432

Suitable for	
gallery	
Sustainability	
Halogen free	Yes
RoHS conform	Yes