


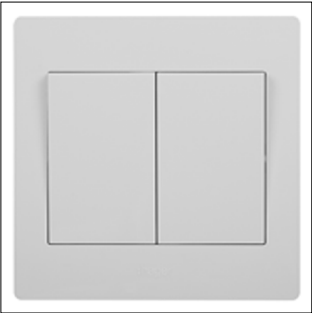

WGML121

16AX 2G 1W switch

Technical Features

|                         |      |
|-------------------------|------|
| <b>Electric current</b> |      |
| Switching current       | 16 A |

|                               |                |
|-------------------------------|----------------|
| <b>Installation, mounting</b> |                |
| Mounting on                   | Flush mounting |

|                |       |
|----------------|-------|
| <b>Voltage</b> |       |
| Rated voltage  | 250 V |

|                  |                    |
|------------------|--------------------|
| <b>Materials</b> |                    |
| Colour           | White              |
| Surface finish   | Glossy             |
| Material         | Polycarbonate (PC) |
| Treatment        | Untreated          |

|                     |                |
|---------------------|----------------|
| <b>Connectivity</b> |                |
| Mounting type       | Screw mounting |

|                                |   |
|--------------------------------|---|
| <b>Controls and indicators</b> |   |
| Number of buttons              | 2 |

|                                    |            |
|------------------------------------|------------|
| <b>Dimensions</b>                  |            |
| Dimensions                         | 86 x 86 mm |
| Built-in depth flush-mounted boxes | 35 mm      |

|                               |      |
|-------------------------------|------|
| <b>Safety</b>                 |      |
| Ingress Protection (IP) class | IP20 |

|                           |               |
|---------------------------|---------------|
| <b>Architecture</b>       |               |
| Control/operation element | Double rocker |

|                         |      |
|-------------------------|------|
| <b>Electric current</b> |      |
| Rated current           | 16 A |

|              |                                          |
|--------------|------------------------------------------|
| <b>Texts</b> |                                          |
| Lighting     | Without lighting (cannot be illuminated) |
| Switch mode  | 1-way                                    |

|                       |     |
|-----------------------|-----|
| <b>Sustainability</b> |     |
| REACH-SVHC free       | Yes |
| RoHS conform          | Yes |