




53420216

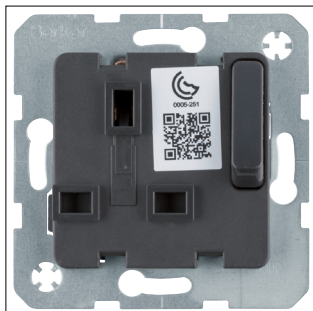

Soc.out. insert earth. contact BRIT.ST.,can be switched off,enhncd contact prot.

Technical Features

Voltage

Rated voltage 250 V

Electric current

Rated current 13 A

Frequency

Frequency 50 - 60 Hz

Materials

Colour	Anthracite
RAL code	7021
Surface finish	Glossy
Material	Thermoplastic
Treatment	Untreated

Dimensions

Height	71 mm
Width	71 mm
Built-in depth flush-mounted boxes	40 mm

Installation, mounting

Mounting on Flush mounting

Connectivity

Type of connection	Screw terminal
Mounting type	Screw mounting Claw mounting

Equipment

Connector/plug type socket outlet	British Standard
Rotated central insert	No
With hinged lid	No
With round protective earth pin	No
With signal lamp	No
With lock	No

Accessories

Has labelling field No

Capacity

Number of modules 1

Safety

With enhanced contact protection	No
Impact resistance IK	IK02
Ingress Protection (IP) class	IP20

Functions

With orientation lighting	No
With function lighting	No

Texts

Imprint	Without imprint
Cover	Central cover plate
Protection	Enhanced contact protection
Type of connection	With screw terminals

Sustainability

Halogen free	Yes
RoHS conform	Yes