


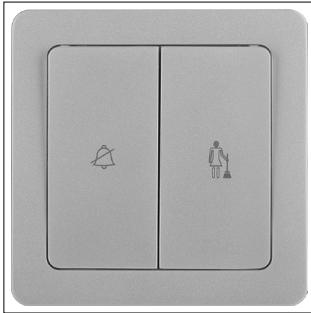

WGCXHDCAS

16AX DND&MUR SWITCH W/ LED (INDOOR), AS

Technical Features

Electric current

Switching current	16 A
-------------------	------

Voltage

Rated voltage	250 V
---------------	-------

Frequency

Frequency	50 - 60 Hz
-----------	------------

Materials

Colour	Aurora silver
Surface finish	Matt
Treatment	Varnished

Controls and indicators

Number of buttons	2
-------------------	---

Dimensions

Dimensions	86 x 86 mm
------------	------------

Safety

Ingress Protection (IP) class	IP20
-------------------------------	------

Architecture

Control/operation element	Double push button
---------------------------	--------------------

Electric current

Rated current	16 A
---------------	------

Texts

Switch mode	2-way
-------------	-------

Sustainability

REACH-SVHC free	Yes
RoHS conform	Yes