


Product Datasheet

503503

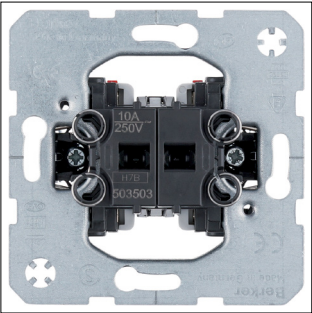

503503



Double mom. Cont. Switch

Technical Features

Electric current

Switching current	10 A
Momentary contact current	10 A

Voltage

Rated voltage	250 V
---------------	-------

Architecture

Control/operation element	Double rocker
---------------------------	---------------

Materials

Material	Metal Plastic
Treatment	Untreated
Transparent	No

Dimensions

Height	71 mm
Width	71 mm
Depth	41.60 mm
Built-in depth	31.70 mm
Built-in depth flush-mounted boxes	35 mm

Installation, mounting

Mounting on	Flush mounting
-------------	----------------

Controls and indicators

Number of buttons	2
Type of push button	Series push button
With feedback signal contact	No

Connectivity

Type of connection	quickconnect
--------------------	--------------

Safety

Ingress Protection (IP) class	IP20
Impact resistance IK	IK07

Texts

Imprint	Without imprint
Installation mode	With spreader claws
Lighting	Can be illuminated using neon lamp, incandescent or LED unit with N terminal For lighting and monitoring circuit
Switch mode	2NO contacts, separate input terminals
Type of connection	With plug-in terminals

Suitable for

K.x / Q.x / R.x / S.x/B.x

Sustainability

Halogen free	Yes
RoHS conform	Yes