


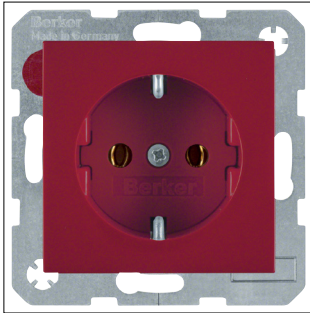

47438912

## SCHUKO soc. out., S.1/B.3/B.7, red glossy

### Technical Features

#### Voltage

|               |       |
|---------------|-------|
| Rated voltage | 250 V |
|---------------|-------|

#### Electric current

|               |      |
|---------------|------|
| Rated current | 16 A |
|---------------|------|

#### Frequency

|           |            |
|-----------|------------|
| Frequency | 50 - 60 Hz |
|-----------|------------|

#### Materials

|                |             |
|----------------|-------------|
| Colour         | Red         |
| RAL code       | 3003        |
| Surface finish | Glossy      |
| Material       | Duroplastic |
| Treatment      | Untreated   |

#### Dimensions

|                                    |       |
|------------------------------------|-------|
| Height                             | 71 mm |
| Width                              | 71 mm |
| Number of units                    | 1     |
| Built-in depth flush-mounted boxes | 31 mm |
| Built-in depth                     | 32 mm |

#### Connection

|                     |                  |
|---------------------|------------------|
| Connector/plug type | Plug-in terminal |
|---------------------|------------------|

#### Installation, mounting

|             |                |
|-------------|----------------|
| Mounting on | Flush mounting |
|-------------|----------------|

#### Connectivity

|                    |                                 |
|--------------------|---------------------------------|
| Type of connection | Plug-in connection              |
| Mounting type      | Screw mounting<br>Claw mounting |

#### Equipment

|                                   |        |
|-----------------------------------|--------|
| Connector/plug type socket outlet | SCHUKO |
| Rotated central insert            | No     |
| With hinged lid                   | No     |
| With round protective earth pin   | No     |
| With signal lamp                  | No     |
| With lock                         | No     |

#### Accessories

|                     |    |
|---------------------|----|
| Has labelling field | No |
|---------------------|----|

#### Capacity

|                   |   |
|-------------------|---|
| Number of modules | 1 |
|-------------------|---|

#### Safety

|                                  |      |
|----------------------------------|------|
| With enhanced contact protection | No   |
| Impact resistance IK             | IK02 |
| Ingress Protection (IP) class    | IP20 |

#### Functions

|                           |    |
|---------------------------|----|
| With orientation lighting | No |
| With function lighting    | No |

#### Identification

|              |    |
|--------------|----|
| With imprint | No |
|--------------|----|

|                    |                                     |
|--------------------|-------------------------------------|
| <b>Texts</b>       |                                     |
| Cover              | Central cover plate                 |
| Protection         | Without enhanced contact protection |
| Type of connection | With plug-in terminals              |

|                     |  |
|---------------------|--|
| <b>Suitable for</b> |  |
| S.x/B.x             |  |

|                       |     |
|-----------------------|-----|
| <b>Sustainability</b> |     |
| Halogen free          | Yes |
| RoHS conform          | Yes |