


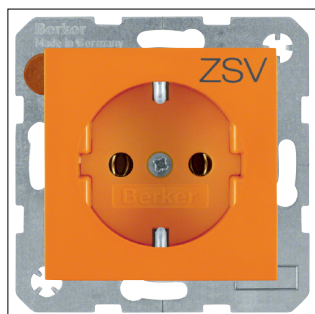

47438907

SCHUKO soc. out. "ZSV" imprint, S.1/B.3/B.7, orange glossy

Technical Features

Voltage

Rated voltage 250 V

Electric current

Rated current 16 A

Frequency

Frequency 50 - 60 Hz

Materials

Colour	Orange
RAL code	2003
Surface finish	Glossy
Material	Duroplastic
Treatment	Untreated

Dimensions

Height	71 mm
Width	71 mm
Number of units	1
Built-in depth flush-mounted boxes	31 mm
Built-in depth	32 mm

Connection

Connector/plug type Plug-in terminal

Installation, mounting

Mounting on Flush mounting

Connectivity

Type of connection	Plug-in connection
Mounting type	Screw mounting Claw mounting

Equipment

Connector/plug type socket outlet	SCHUKO
Rotated central insert	No
With hinged lid	No
With round protective earth pin	No
With signal lamp	No
With lock	No

Accessories

Has labelling field No

Capacity

Number of modules 1

Safety

With enhanced contact protection	No
Impact resistance IK	IK02
Ingress Protection (IP) class	IP20

Functions

With orientation lighting	No
With function lighting	No

Texts

Imprint	With imprint "ZSV"
Cover	Central cover plate

Texts	
Protection	Without enhanced contact protection
Type of connection	With plug-in terminals
Suitable for	
S.x/B.x	
Sustainability	
Halogen free	Yes
RoHS conform	Yes