


Product Datasheet

75142830

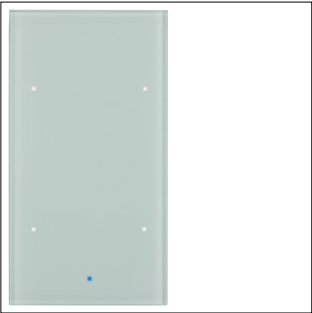

75142830



IP20

KNX glass sensor 2gang comf, intg bus coupl. unit, KNX-TS sensor, glass p.white

Technical Features

Installation, mounting

Mounting on Flush mounting

Use conditions

Operating temperature -5 - 45 °C

Functions

With room temperature controller Yes

Power

Current consumption 12.50 mA

Dimensions

Built-in depth 24.20 mm
Built-in depth flush-mounted boxes 27 mm
Height 160 mm
Width 86 mm
Depth 37.70 mm

Equipment

Number of actuation points 4

Controls and indicators

With LED indication Yes

Materials

Colour Polar white
RAL code 9010
Material Glass
Surface finish Glossy Matt

Accessories

Has labelling field No

Screen

With display No

Texts

Function For switch, push-button, dimmer and shutter functions
Blocking function for sensor surface e.g. for cleaning the glass surface
Installation mode For vertical mounting
Temperature Additional connection for external temperature sensor
Integrated temperature sensor for operation as controller extension unit
Temperature measurement via internal Temperature sensor or external communication object

Sustainability

REACH-SVHC free Yes
RoHS conform Yes