


# Product Datasheet

## DAS2453300ELN

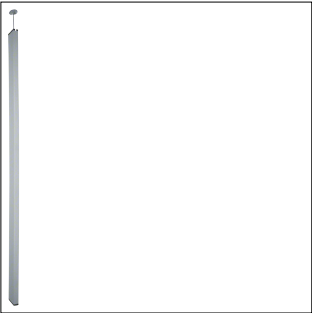

DAS2453300ELN

DA200 double, pressure fitting 3,3 - 3,6 m, Alu naturel anodized

Technical Features

Dimensions

|                     |                             |
|---------------------|-----------------------------|
| Depth               | 132 mm                      |
| Width               | 132 mm                      |
| Installation height | 3.3 - 3.6 m                 |
| Height adjustment   | 300 mm                      |
| Inner cross-section | 4300 - 4300 mm <sup>2</sup> |
| Pole shape          | Rectangular                 |
| Lid width           | 45 mm                       |

Cover, door

|                          |   |
|--------------------------|---|
| Number of mountable lids | 2 |
|--------------------------|---|

Equipment

|             |     |
|-------------|-----|
| Adjustable  | Yes |
| Is portable | No  |

Cable

|                      |     |
|----------------------|-----|
| Cable entry position | Top |
|----------------------|-----|

Installation, mounting

|                              |     |
|------------------------------|-----|
| Ceiling mounting possible    | Yes |
| Suitable for ground mounting | Yes |

Materials

|           |           |
|-----------|-----------|
| Material  | Aluminium |
| Treatment | Anodised  |
| Colour    | Aluminium |

Configuration

|                                  |             |
|----------------------------------|-------------|
| Number of sides for installation | Double side |
|----------------------------------|-------------|

Sustainability

|              |     |
|--------------|-----|
| RoHS conform | Yes |
|--------------|-----|

Illustrations | Drawings

