


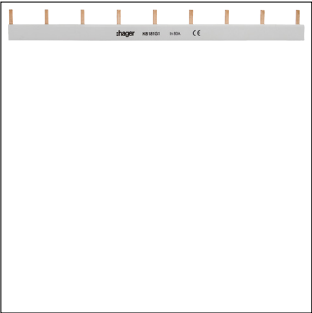

KB181G1

Insulated prong busbar 1P 80A 16mm² 6C for RCBO

Technical Features

Electric current

Rated current	80 A
---------------	------

Architecture

Number of poles	1
-----------------	---

Dimensions

Length	184 mm
--------	--------

Voltage

Rated impulse withstand voltage U _{imp}	4000 V
Rated operational voltage U _e	415 - 415 V

Connection

Cross-section rigid conductor	16 mm ²
Connector/plug type	Phase busbar with pin

Capacity

Number of modules	11
-------------------	----

Sustainability

REACH-SVHC free	Yes
RoHS conform	Yes