




75740101

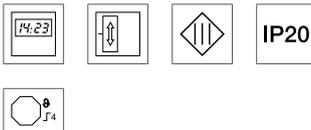

KNX Touch Control TFT display, intg bus coupling unit, KNX, black glossy

Technical Features

Installation, mounting

Mounting on Flush mounting

Use conditions

Operating temperature 0 - 50 °C

Electric current

Bus current consumption data transfer 10 mA

Dimensions

Built-in depth 25.50 mm
 Built-in depth flush-mounted boxes 29 mm
 Height 75 mm
 Width 95 mm
 Depth 44 mm

Equipment

Number of actuation points 6

Materials

Colour Black
 RAL code 9005
 Material Metal
Plastic
 Surface finish Glossy

Screen

With display Yes

Texts

Function 16 time switching functions and alarm clock
 Logic modules: 4x AND, 4x OR with 4 inputs each
 Functions such as switching, dimming, blind control, up
 to 16 scenes, climate control, activation of alarm systems,
 date, time of day
 Automatic function for control of lighting, blinds and roller
 shutters, air conditioning and ventilation systems
 Disabling function for cleaning the user interface

Sustainability

REACH-SVHC free Yes
 RoHS conform Yes