


# Product Datasheet

## 75740101



75740101

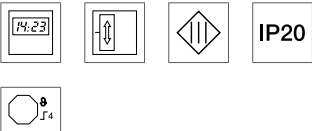

### KNX Touch Control TFT display, intg bus coupling unit, KNX, black glossy

#### Technical Features

#### Installation, mounting

Mounting on	Flush mounting
-------------	----------------

#### Use conditions

Operating temperature	0 - 50 °C
-----------------------	-----------

#### Electric current

Bus current consumption data transfer	10 mA
---------------------------------------	-------

#### Dimensions

Built-in depth	25.50 mm
Built-in depth flush-mounted boxes	29 mm
Height	75 mm
Width	95 mm
Depth	44 mm

#### Equipment

Number of actuation points	6
----------------------------	---

#### Materials

Colour	Black
RAL code	9005
Material	Metal Plastic
Surface finish	Glossy

#### Screen

With display	Yes
--------------	-----

#### Texts

Function	16 time switching functions and alarm clock Logic modules: 4x AND, 4x OR with 4 inputs each Functions such as switching, dimming, blind control, up to 16 scenes, climate control, activation of alarm systems, date, time of day Automatic function for control of lighting, blinds and roller shutters, air conditioning and ventilation systems Disabling function for cleaning the user interface
----------	---

#### Sustainability

REACH-SVHC free	Yes
RoHS conform	Yes