


Product Datasheet

WBHP2XSB-MW

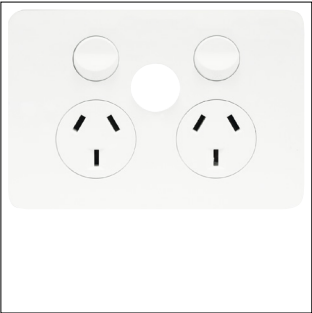

WBHP2XSB-MW

Allure DGPO 10A XS Pos no mech MW

Technical Features

| | |
|-------------------------|------|
| Electric current | |
| Rated current | 10 A |

| | |
|-----------------|-------------|
| Voltage | |
| Nominal voltage | 250 - 250 V |

| | |
|------------------|-------|
| Materials | |
| Colour | White |

| | |
|---------------------|----------------|
| Connectivity | |
| Mounting type | Screw mounting |

| | |
|-----------------------------------|---------------------------------|
| Equipment | |
| Connector/plug type socket outlet | Australian standard AS/NZS 3112 |
| Rotated central insert | No |
| With hinged lid | No |

| | |
|-------------------------------|------|
| Safety | |
| Ingress Protection (IP) class | IP2X |

| | |
|--------------------|----------------------|
| Texts | |
| Cover | Full cover plate |
| Type of connection | With screw terminals |

| | |
|---------------------|--|
| Suitable for | |
| allure | |

| | |
|-----------------------|-----|
| Sustainability | |
| Halogen free | Yes |
| REACH-SVHC free | Yes |
| RoHS conform | Yes |