


Product Datasheet

WGDL111NP-12VEG

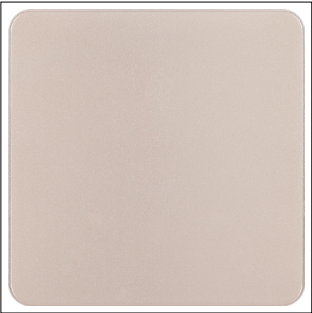

WGDL111NP-12VEG

12V 1G press switch with led;eg

Technical Features

Electric current	
Switching current	10 A
Voltage	
Rated voltage	250 V
Frequency	
Frequency	50-60 Hz
Architecture	
Control/operation element	Single rocker
Number of poles	1
Power	
Fluorescent lamps in duo circuit	0 W
Materials	
Colour	Gold
Surface finish	Matt
Material	Polycarbonate (PC)
Treatment	Varnished
Transparent	No
Dimensions	
Height	22 mm
Width	90 mm
Depth	25 mm
Built-in depth	25 mm
Installation, mounting	
Mounting on	Wall mounting
Controls and indicators	
Number of buttons	1
Connectivity	
Type of connection	Screw terminal
Safety	
Ingress Protection (IP) class	IP20
Impact resistance IK	IK02
Texts	
Switch mode	1-way
Suitable for	
shark	
Sustainability	
RoHS conform	Yes