


Product Datasheet

HXA024H

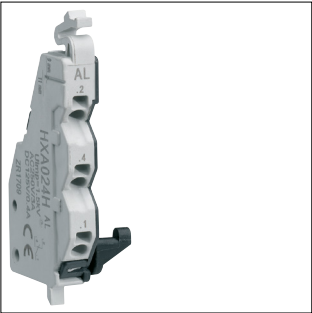

HXA024H

Alarm contact 1NO+1NC 250V AC (x160-P160-x250-P250-x630-P630)

Technical Features

Electric current	
Rated current	3 A
Rated current 230 V AC15	3 A

Connectivity	
Type of connection	quickconnect
Mounting type	Click mounting

Connection	
Type of contacts	1NC+1NO
Cross-section flexible conductor	0.5 - 1.25 mm ²
Cross-section rigid conductor	0.5 - 1.25 mm ²

Voltage	
Rated impulse withstand voltage Uimp	1500 V
Type voltage supply	AC/DC

Power	
Total power loss under IN	3 W

Equipment	
Number of INV contacts	0
Number of NC contacts	1

Safety	
Ingress Protection (IP) class	IP4X

Sustainability	
RoHS conform	Yes