


# Product Datasheet

## WGDL111NP-12VKB

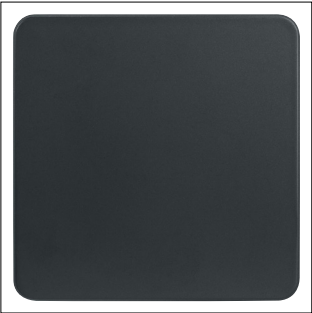

WGDL111NP-12VKB

### 12V 1G press switch with led;kb

#### Technical Features

<b>Electric current</b>	
Switching current	10 A

<b>Voltage</b>	
Rated voltage	250 V

<b>Frequency</b>	
Frequency	50-60 Hz

<b>Architecture</b>	
Control/operation element	Single rocker
Number of poles	1

<b>Power</b>	
Fluorescent lamps in duo circuit	0 W

<b>Materials</b>	
Colour	Knight black
Surface finish	Matt
Material	Polycarbonate (PC)
Treatment	Varnished
Transparent	No

<b>Dimensions</b>	
Height	22 mm
Width	90 mm
Depth	25 mm
Built-in depth	25 mm

<b>Installation, mounting</b>	
Mounting on	Wall mounting

<b>Controls and indicators</b>	
Number of buttons	1

<b>Connectivity</b>	
Type of connection	Screw terminal

<b>Safety</b>	
Ingress Protection (IP) class	IP20
Impact resistance IK	IK02

<b>Texts</b>	
Switch mode	1-way

<b>Suitable for</b>	
shark	

<b>Sustainability</b>	
RoHS conform	Yes