


Product Datasheet

WGDL111NP-12VKB

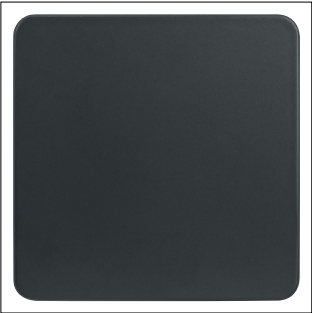

WGDL111NP-12VKB

12V 1G press switch with led;kb

Technical Features

Electric current	
Switching current	10 A

Voltage	
Rated voltage	250 V

Frequency	
Frequency	50-60 Hz

Architecture	
Control/operation element	Single rocker
Number of poles	1

Power	
Fluorescent lamps in duo circuit	0 W

Materials	
Colour	Knight black
Surface finish	Matt
Material	Polycarbonate (PC)
Treatment	Varnished
Transparent	No

Dimensions	
Height	22 mm
Width	90 mm
Depth	25 mm
Built-in depth	25 mm

Installation, mounting	
Mounting on	Wall mounting

Controls and indicators	
Number of buttons	1

Connectivity	
Type of connection	Screw terminal

Safety	
Ingress Protection (IP) class	IP20
Impact resistance IK	IK02

Texts	
Switch mode	1-way

Suitable for	
shark	

Sustainability	
RoHS conform	Yes