


Product Datasheet

503404

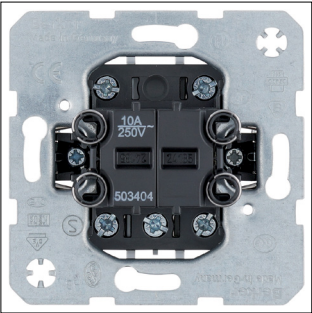

503404



Group push-button, 4NO contacts, comm. input terminal, neut. pos., light control

Technical Features

Electric current

Switching current	10 A
Momentary contact current	10 A

Voltage

Rated voltage	250 V
---------------	-------

Architecture

Control/operation element	Double rocker
Number of poles	0

Materials

Surface finish	Matt
Material	Metal Plastic
Treatment	Untreated
Transparent	No

Dimensions

Height	71 mm
Width	71 mm
Depth	41.60 mm
Built-in depth flush-mounted boxes	35 mm

Installation, mounting

Mounting on	Flush mounting
-------------	----------------

Controls and indicators

Number of buttons	2
Type of push button	Group push button
With feedback signal contact	No

Connectivity

Type of connection	Screw terminal
--------------------	----------------

Safety

Ingress Protection (IP) class	IP20
Impact resistance IK	IK07

Texts

Imprint	Without imprint
Installation mode	With spreader claws
Lighting	For illumination
Switch mode	With neutral position
Type of connection	With screw terminals

Suitable for

K.x / Q.x / R.x / S.x/B.x

Sustainability

RoHS conform	Yes
--------------	-----