


# Product Datasheet

## HXA021H

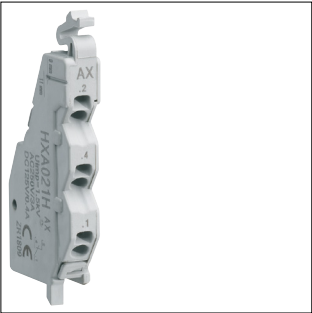

HXA021H

Auxiliary contact 1NO+1NC 250V AC (x160-P160-x250-P250-x630-P630)

Technical Features

|                               |                |
|-------------------------------|----------------|
| <b>Electric current</b>       |                |
| Rated current 230 V AC15      | 3 A            |
| <b>Connectivity</b>           |                |
| Type of connection            | quickconnect   |
| Mounting type                 | Click mounting |
| <b>Connection</b>             |                |
| Type of contacts              | 1NC+1NO        |
| <b>Voltage</b>                |                |
| Type voltage supply           | AC/DC          |
| <b>Power</b>                  |                |
| Total power loss under IN     | 3 W            |
| <b>Equipment</b>              |                |
| Number of INV contacts        | 0              |
| Number of NC contacts         | 1              |
| <b>Safety</b>                 |                |
| Ingress Protection (IP) class | IP4X           |
| <b>Sustainability</b>         |                |
| REACH-SVHC free               | Yes            |
| RoHS conform                  | Yes            |