


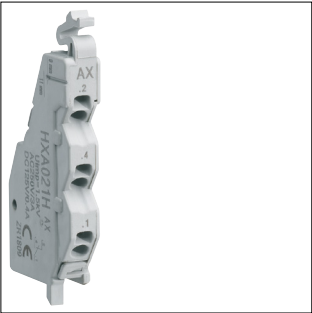

HXA021H

Auxiliary contact 1NO+1NC 250V AC (x160-P160-x250-P250-x630-P630)

Technical Features

Electric current	
Rated current 230 V AC15	3 A
Connectivity	
Type of connection	quickconnect
Mounting type	Click mounting
Connection	
Type of contacts	1NC+1NO
Voltage	
Rated insulation voltage Ui	250 V
Rated impulse withstand voltage Uimp	1500 V
Type voltage supply	AC/DC
Power	
Total power loss under IN	3 W
Equipment	
Number of INV contacts	0
Number of NC contacts	1
Safety	
Ingress Protection (IP) class	IP4X
Sustainability	
REACH-SVHC free	Yes
RoHS conform	Yes