




75642165

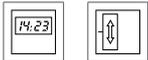

Touch sensor 2gang thermostat, display, intg bus coupl. unit,KNX-R.1, glass bl.

Technical Features

Installation, mounting

Mounting on Flush mounting

Use conditions

Operating temperature -5 - 45 °C

Functions

With room temperature controller Yes

Power

Current consumption 23 mA

Dimensions

Built-in depth 12.90 mm
 Built-in depth flush-mounted boxes 16 mm
 Height 152 mm
 Width 81 mm
 Depth 23 mm

Equipment

Number of actuation points 4

Controls and indicators

With LED indication Yes

Materials

Colour Black
 RAL code 9005
 Material Glass
 Surface finish Glossy

Accessories

Has labelling field No

Screen

With display Yes

Texts

Function For switch, push-button, dimmer, blind and thermostat functions
 With valve protection function
 Installation mode For vertical mounting
 Operating mode Controller operating modes: comfort, standby, night and frost/heat protection mode
 Temperature Additional connection for external temperature sensor
 Temperature measurement via internal Temperature sensor or external communication object
 Voltage Operation with non-choked output of KNX voltage supply possible (pay attention to current consumption)
 Separate auxiliary power supply needed

Sustainability

REACH-SVHC free Yes
 RoHS conform Yes