


Product Datasheet

2873

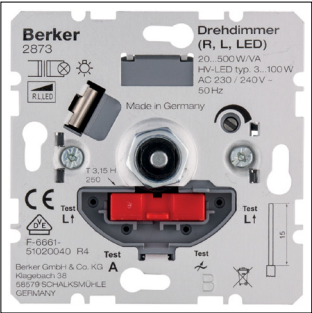

2873



Rotary dimmer LV with soft-lock house electronics

Technical Features

Voltage

Operating voltage	230 - 230 V
-------------------	-------------

Frequency

Frequency	50 - 50 Hz
-----------	------------

Electric current

Control current	100 - 100 mA
-----------------	--------------

Materials

Material	Metal Plastic
----------	------------------

Dimensions

Diameter axis	4 mm
Height	82 mm
Width	82 mm
Depth	67 mm

Architecture

Control/operation element	Push & rotative switch
---------------------------	------------------------

Lighting

Dimmable 230 V LED lamp	3 - 100 W
-------------------------	-----------

Texts

Dimming principle	Phase cut-on
Fuse	Short-circuit and overload-proof (fine-wire fuse) With spare fuse
Voltage	Voltage test possible without dismantling
Installation mode	With spreader claws
Type of connection	With plug-in terminals
Operation and control	No Bluetooth interface
Terminal	With terminal for base load from mains isolator

Sustainability

REACH-SVHC free	Yes
RoHS conform	Yes