


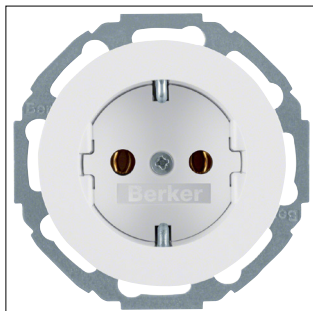

47272089

SCHUKO soc. out. 45°, R.1/R.3, p. white glossy

Technical Features

Electric current

Rated current	16 A
---------------	------

Voltage

Rated voltage	250 V
---------------	-------

Nominal voltage	250 - 250 V
-----------------	-------------

Frequency

Frequency	50 - 60 Hz
-----------	------------

Materials

Colour	Polar white
--------	-------------

RAL code	9010
----------	------

Surface finish	Glossy
----------------	--------

Material	Thermoplastic
----------	---------------

Treatment	Untreated
-----------	-----------

Dimensions

Height	71 mm
--------	-------

Width	71 mm
-------	-------

Depth	40.80 mm
-------	----------

Number of units	1
-----------------	---

Built-in depth	32 mm
----------------	-------

Connection

Connector/plug type	Plug-in terminal
---------------------	------------------

Installation, mounting

Mounting on	Flush mounting
-------------	----------------

Connectivity

Type of connection	Plug-in connection
--------------------	--------------------

Mounting type	Screw mounting Claw mounting
---------------	---------------------------------

Equipment

Connector/plug type socket outlet	SCHUKO
-----------------------------------	--------

Rotated central insert	Yes
------------------------	-----

With hinged lid	No
-----------------	----

With round protective earth pin	No
---------------------------------	----

With signal lamp	No
------------------	----

With lock	No
-----------	----

Accessories

Has labelling field	No
---------------------	----

Capacity

Number of modules	1
-------------------	---

Safety

With enhanced contact protection	No
----------------------------------	----

Impact resistance IK	IK05
----------------------	------

Ingress Protection (IP) class	IP20
-------------------------------	------

Functions

With orientation lighting	No
---------------------------	----

With function lighting	No
------------------------	----

Product Datasheet

47272089

Texts

Imprint	Without imprint
Cover	Central cover plate
Protection	Without enhanced contact protection
Type of connection	With plug-in terminals

Suitable for

R.x

Sustainability

Halogen free	Yes
RoHS conform	Yes