


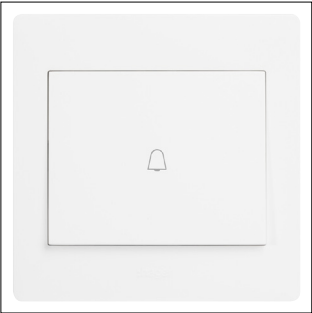

WGML111B

10A 1G bell switch mark bell symbol

Technical Features

Electric current	
Switching current	10 A

Voltage	
Rated voltage	250 V

Architecture	
Control/operation element	Single rocker

Materials	
Colour	White
Surface finish	Glossy
Material	Polycarbonate (PC)
Treatment	Untreated
Transparent	No

Dimensions	
Height	86 mm
Width	86 mm
Depth	25 mm
Built-in depth flush-mounted boxes	35 mm

Installation, mounting	
Mounting on	Flush mounting

Controls and indicators	
Number of buttons	1
With feedback signal contact	No

Connectivity	
Type of connection	Screw terminal

Safety	
Ingress Protection (IP) class	IP20

Accessories	
Has labelling field	No

Texts	
Imprint	With imprinted symbol bell

Suitable for	
shark	

Sustainability	
REACH-SVHC free	Yes
RoHS conform	Yes