


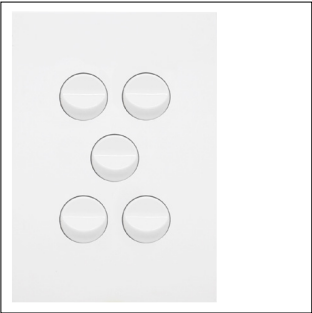

WBQSV5

**FIN 5 Gang Switch Plate cw mechs**

**Technical Features**

**Installation, mounting**

|             |                |
|-------------|----------------|
| Mounting on | Flush mounting |
|-------------|----------------|

**Frequency**

|           |            |
|-----------|------------|
| Frequency | 50 - 50 Hz |
|-----------|------------|

**Materials**

|        |       |
|--------|-------|
| Colour | White |
|--------|-------|

**Identification**

|                      |                                     |
|----------------------|-------------------------------------|
| Assembly arrangement | Basic element with full cover plate |
|----------------------|-------------------------------------|

**Connectivity**

|               |                |
|---------------|----------------|
| Mounting type | Screw mounting |
|---------------|----------------|

**Controls and indicators**

|                   |   |
|-------------------|---|
| Number of buttons | 5 |
|-------------------|---|

**Dimensions**

|            |             |
|------------|-------------|
| Dimensions | 82 x 120 mm |
|------------|-------------|

**Electric current**

|                  |      |
|------------------|------|
| Rated current IN | 16 A |
|------------------|------|

**Texts**

|                    |                                          |
|--------------------|------------------------------------------|
| Installation mode  | For screw fastening                      |
| Type of connection | With screw terminals                     |
| Lighting           | Without lighting (cannot be illuminated) |
| Push button        | No                                       |

**Sustainability**

|                 |     |
|-----------------|-----|
| Halogen free    | Yes |
| REACH-SVHC free | Yes |
| RoHS conform    | Yes |