


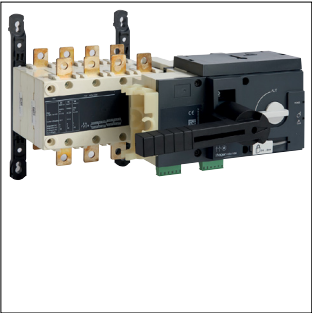

HIB416M

Motorized transfer switch 4P 200A

Technical Features

Voltage

Rated operational voltage U_e	380 - 690 V
---------------------------------	-------------

Electric current

Rated current	200 A
Rated conditional short-circuit current I_{cc} with gl-gG fuses	50 kA

Power

Rated operational power under 400 V AC AC1	131000 W
--	----------

Architecture

Number of poles	4
Device construction type	Fixed built-in

Compatibility

Suitable for DIN Rail	No
Suitable for distribution board	Yes

Installation, mounting

Mounting on	Mounting plate
-------------	----------------